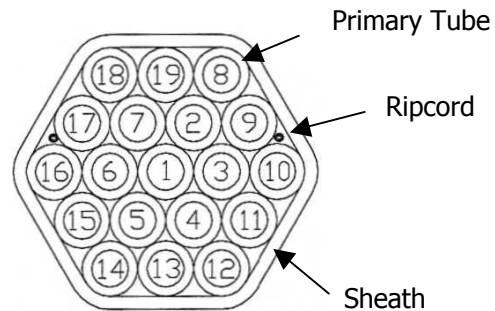
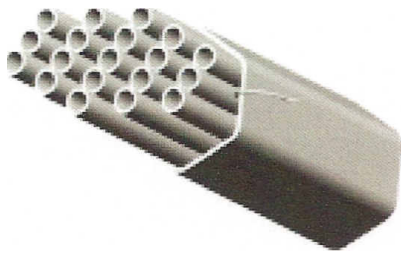


# Sirocco Riser Rated Tube Cables (OFNR)

Prysmian Part Number: See Table Below



**Field assembled micro-duct cable rated for indoor blown fiber installations. This cable is suitable for "Riser" applications where flame propagation characteristics are required in accordance with NEC article 770-51(b) and NEC 770-53(b). The cable is UL Listed type OFNR**

- Low friction internal coating for maximum fiber blowing distance of 2, 4, 8 or 12 single-mode or multimode fiber optic bundles.
- Tube Cable configurations available: 1, 2, 4, 7, 12, 19 & 24 way.
- Each primary tube is 5 mm OD x 3.5 mm ID.
- Solid white / cream colored tubes.
- Print details includes batch number, meter count and individual tube number.
- Supplied on wooden reels.

Assembly Type	Product Code	O.D. (Nominal) (mm)	Ripcord Qty	Min. Bend Radius (mm)	Max Tensile (N)	Nominal Weight (g/m)	Reel Lengths (m)
1 way	ULR0501	7.5	1	80	180	35	500, 1000, 2000, 4000
2 way	ULR0502	7.0 x 12.0	1	80	360	55	500, 1000, 2000, 4000
4 way	ULR0504	12.0 x 14.5	2	125	580	93	500, 1000, 2000, 4000
7 way	ULR0507	15.7 x 17	2	180	860	144	500, 1000, 2000, 4000
12 way	ULR0512	20 x 20.3	2	220	1300	227	500, 1000, 2000, 4000
19 way	ULR0519	24.0 x 28	2	300	1900	338	500, 1000, 2000, 4000
24 way	ULR0524	31.0 x 33.0	2	340	2500	462	500, 1000, 2000, 4000

Prysmian Cables & Systems, 700 Industrial Drive, Lexington, SC 29072











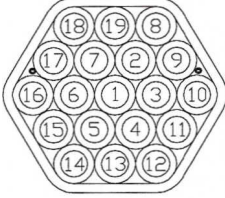
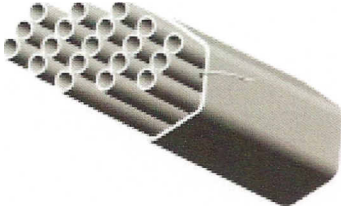
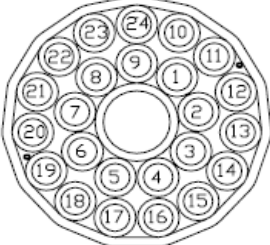
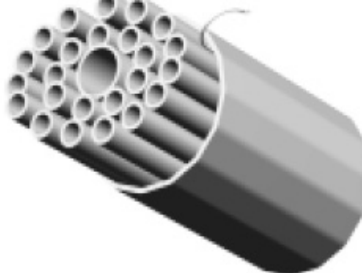
Technical Inquiries 803-951-4055 Fax Number 803-951-4628

© PRYSMIAN 2007. All Rights Reserved.

The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian. The information is believed correct at the time of issue. Prysmian reserves the right to amend this specification without notice. This specification is not contractually valid unless specifically authorized by Prysmian.

**Issue 01, April 9, 2007**  
Ref: ST009-01

## Sirocco Riser Rated Tube Cables (OFNR)

	<b>1 way</b>	
	<b>2 way</b>	
	<b>4 way</b>	
	<b>7 way</b>	
	<b>12 way</b>	
	<b>19 way</b>	
	<b>24 way</b>	

Prysmian Cables & Systems, 700 Industrial Drive, Lexington, SC 29072

Technical Inquiries 803-951-4055 Fax Number 803-951-4628

© PRYSMIAN 2007. All Rights Reserved.

The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian. The information is believed correct at the time of issue. Prysmian reserves the right to amend this specification without notice. This specification is not contractually valid unless specifically authorized by Prysmian.

**Issue 01, April 9, 2007**  
**Ref: ST009-01**