


## Bend Limiting Transport Tube

**Prysmian Part Number: XEXSC00233**

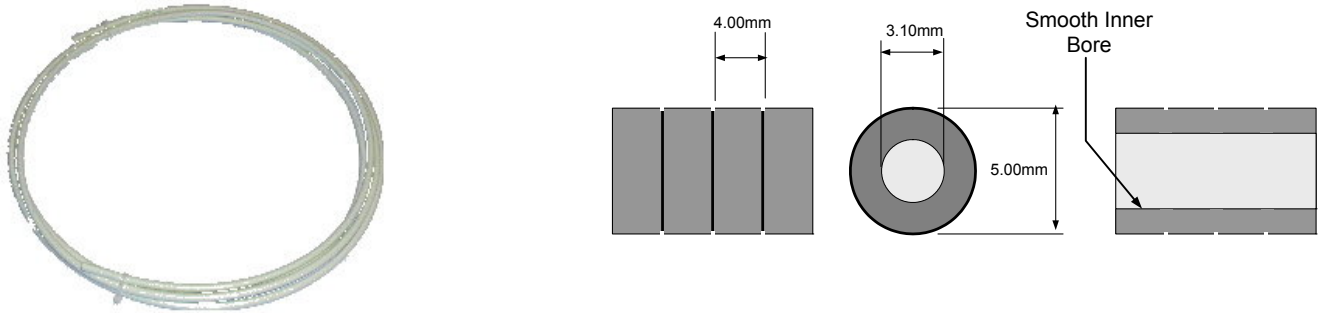

Bend Limiting Transport Tube is supplied in 10m coils for applications where routing of fibre within equipment racks and cable nodes etc is required. The Bend Limiting Tube provides excellent protection in these environments especially where resistance to crushing and kinking are required and fibre bends are limited and maintained to an acceptable radius.

### Features and Benefits

- Smooth bore.
- Bend limitation at a controlled radius of 30mm.
- Suitable for protection of fibre and pigtails up to 2.8mm OD.
- Crush Protection.
- Improved fibre management

### Kit Contents

- 10m Coil of White Bend Limiting Tube  
(Other colours are available on request.)

### Technical Data

- Outer tube Diameter: 5.0mm
- Inner Tube Diameter: 3.1mm
- Segment Spacing: 4.0mm
- Crush Resistance: > 0.5kN (measured over 100mm)
- Distortion: < 0.5mm (measured over 100mm)
- Operating temperature: -20°C to + 40°C (5 to 95% RH)
- Material:- Polypropylene
- Finish:- White (Other Colours available on request)

### Logistics

- Packing Dimensions (mm): Coil Ø 250mm
- Packed Weight (kg): 0.100
- Net weight (kg): 0.093

Please contact your local sales office listed on [www.prysmiangroup.com](http://www.prysmiangroup.com)

© Prysmian Group 2012, All Rights Reserved.  
The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian Group. The information is believed correct at the time of issue. Prysmian Group reserves the right to amend this specification without notice. This specification is not contractually valid unless specifically authorised by Prysmian Group.