

Junction Boxes and Knockout Punches/Plugs

UL LISTED, CSA CERTIFIED AS NOTED


Junction boxes - fully assembled with cover and terminals

Part Number	H x W inches	Depth and Capacity inches • wire count	Standard Package
43-036	13-3/4 x 8-1/2	3-1/4 • 36 terminals, 72 wires	1
43-072	24 x 8-1/2	3-1/4 • 72 terminals, 144 wires	1
43-108	36 x 8-1/2	3-1/4 • 108 terminals, 216 wires	1

Junction boxes have knockouts on top, bottom and sides.

Top/bottom knockouts are 2 and 1-1/2 in - sides are 2, 1-1/2, 3/4 and 1/2 in.

Photo shows box with components that may also be ordered separately.

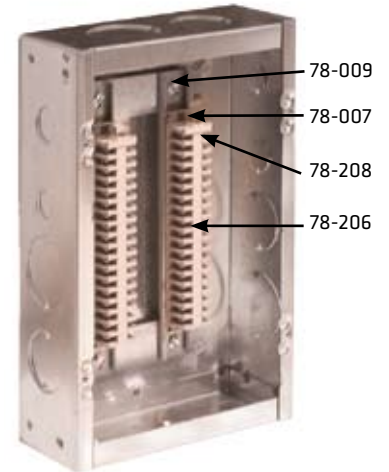

Wireway and Electrical

Junction box components



Part Number	Description	Standard Package
78-206	Tubular terminal clamps (Buchanan 0925) for wire sizes 22 to 10 AWG	100
78-007	Channel clamps (Buchanan 61)	100
78-208	End section (Buchanan 0930)	25
78-009*	Zinc-plated track (Buchanan 60)	6 ft. lengths

*78-009 is not UL listed/CSA certified.



Screw-cover pull boxes - with cover and knockouts



Part Number	H x W inches	Depth inches	K/O Pattern
42-007	4 x 4	4	A
42-006	6 x 6	4	B
42-054	8 x 8	4	B
42-025	10 x 10	4	B
42-051	12 x 12	4	C
42-022	18 x 18	4	D
42-021	24 x 24	4	D
42-055	8 x 8	6	B



Pattern A
1 1/2 - 3/4"

Pattern B
1/2 - 3/4" & 3/4 - 1"

Pattern C
1/2 - 3/4" & 3/4 - 1"

Pattern D
1/2 - 3/4" & 3/4 - 1"

Metal knockout plug

Part Number	Size inches	Standard Package
19-021	1/2	100
19-026	3/4	100
19-027	1	50
19-028	1-1/4	50
19-029	1-1/2	50
19-030	2	2



Standard packaging quantities are listed. Parts may be ordered in less than standard quantities.