


QFC - 4FO Subscriber Cable (Single Jacket)

Prysmian Reference: P7000012 Code: FPTM / K1M

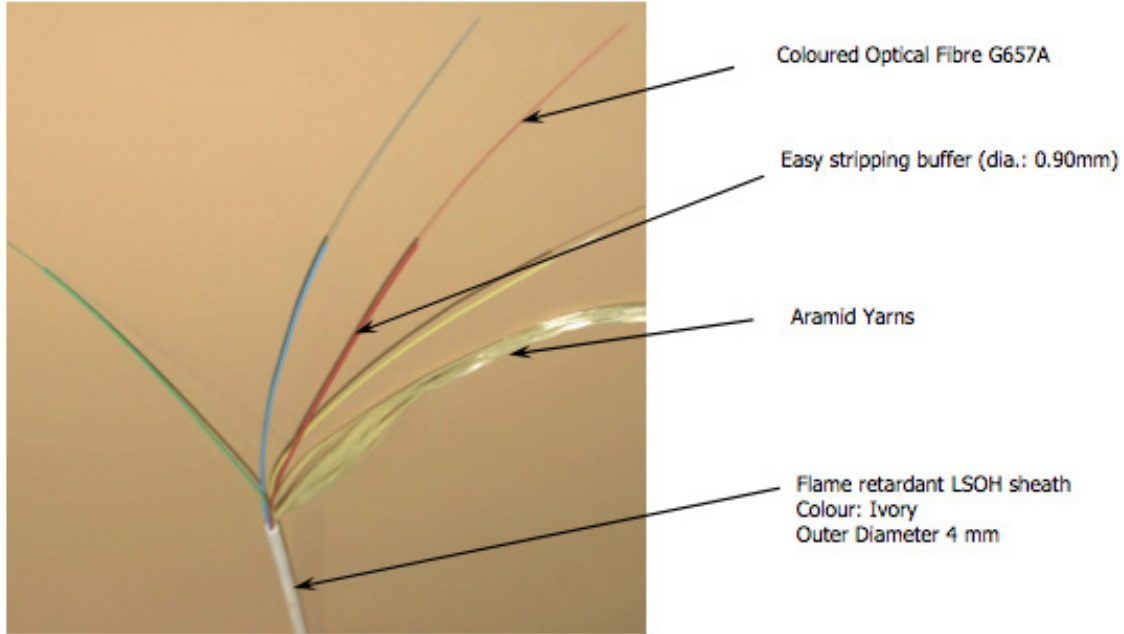

Technical Detail

Cable Diameter	4 mm
Cable Weight (nominal)	16 kg/km
Minimum Bending Radius (operation static)	40 mm
Minimum Bending Radius (dynamic)	80 mm
Tensile Strength (installation)	40 daN
Crush Resistance	80 daN/10cm
Temperature Performance	-10°C + 60°C

Sheath Marking

Without any marking

Colour coding

Red, Blue, Green Yellow

Delivery Length

Standard delivery length: 1000m ± 100m

Up to a maximum of 10% of the total number of cable lengths could be shorter than nominal values

© PRYSMIAN GROUP 2012, All Rights Reserved

All sizes and values without tolerances are reference values. Specifications are for product as supplied by Prysmian Group: any modification or alternation afterwards of product may give different results. The information claimed within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of Prysmian Group. This information is believed to be correct at the time of issue. Prysmian Group reserves the right to amend this specification without prior notice. This specification is not contractually valid unless specifically authorised by Prysmian Group.